

Quick Start Guide

Portable Power Expansion Hub for Apple USB-C Power Adapter

Model: U280-A04-A3C1

USB Type-C™ and USB-C™ are trademarks of USB
Implementers Forum

Este guía esta disponible en español en la página de
Tripp Lite: tripplite.com/support

Ce guide est disponible en français sur le site Web de
Tripp Lite : tripplite.com/support

Русскоязычная версия настоящего краткого
руководства представлена на веб-сайте компании
Tripp Lite по адресу: tripplite.com/support

WARRANTY REGISTRATION

Register your product today and be automatically entered to
win an ISOBAR surge protector in our monthly drawing!

tripplite.com/warranty



1111 W. 35th Street, Chicago, IL 60609 USA
tripplite.com/support

Copyright © 2019 Tripp Lite. All rights reserved.
All trademarks are the property of their respective owners.

Package Includes

- U280-A04-A3C1
- Quick Start Guide

Product Features


- Expand the charging capabilities of an Apple USB-C PD Charger (61W/87W)
- Charge up to 4 USB devices simultaneously*
- Features (x1) USB-C PD 3.0 port with a maximum power output up to 20V/2.25A (45W), (x1) USB-A QC 3.0 port with charging speeds 4x faster than conventional methods, and (x2) USB-A BC 1.2 port supplying up to 5V/2.4A power
- Non-slip grip padding provides a secure connection to the power adapter
- Provides overcharging, overheating, overvoltage and short circuit protection

*45W PD charging port takes priority over all other ports.

Optional Accessories

- U040-C03-C USB 2.0 Type-C to C Cable, 3A, USB-IF Certified (3 ft./0.9 m)
- M100-006-BK USB Sync/Charge Lightning Cable (6 ft./1.8 m).
- U050-003-GY-MAX Heavy-Duty USB 2.0 A to Micro-B Cable, (3 ft./0.9 m)


Feature Identification

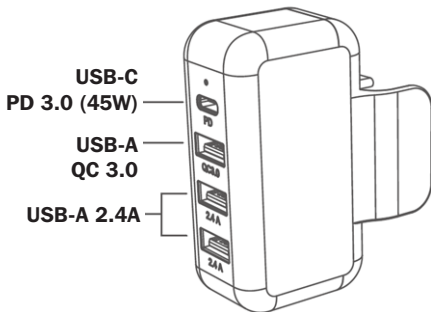

Operation

Notes:

- *This product is recommended for use with Apple MacBook Pro 61W/87W PD chargers.*
 - *Current is equally distributed among all ports. In instances where the full 45W is required from the USB-C PD 3.0 port, the current will be renegotiated to accommodate the USB-C PD 3.0 port first.*
- 1.** Remove the existing USB-C cable on your Apple USB-C PD charger.
 - 2.** Connect the U280-A04-A3C1 hub to the Type-C port PD charger as shown in the figure below. Then, reconnect the USB-C cable to the hub's USB-C PD port.

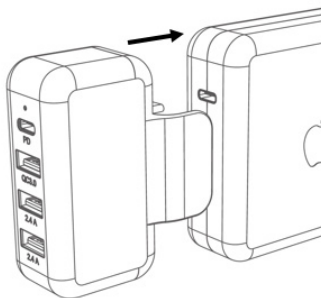

Operation

- The 4-port power expansion hub is now ready to use. A white LED will illuminate to indicate sufficient power is being supplied.

Specifications

| | |
|-------------------------------------|--|
| Input Port | USB-C (Male) |
| Output Ports | (x1) USB-C (Female) (x3) USB-A (Female) |
| Operating Temperature Range | 41°F to 95°F (5°C to 35°C) |
| Storage Temperature Range | -4°F to 122°F (-20°C to 50°C) |
| Relative Humidity | 20% to 80% RH, Non-Condensing |
| PD Charging Specification | PD 3.0 |
| BC 1.2 Compliant Ports | (x2) USB-A |
| Qualcomm Quick Charge Specification | QC 3.0 |

Warranty and Product Registration

2-YEAR LIMITED WARRANTY

TRIPP LITE warrants its products to be free from defects in materials and workmanship for a period of two (2) years from the date of initial purchase. TRIPP LITE's obligation under this warranty is limited to repairing or replacing (at its sole option) any such defective products. To obtain service under this warranty, you must obtain a Returned Material Authorization (RMA) number from TRIPP LITE or an authorized TRIPP LITE service center. Products must be returned to TRIPP LITE or an authorized TRIPP LITE service center with transportation charges prepaid and must be accompanied by a brief description of the problem encountered and proof of date and place of purchase. This warranty does not apply to equipment, which has been damaged by accident, negligence or misapplication or has been altered or modified in any way.

EXCEPT AS PROVIDED HEREIN, TRIPP LITE MAKES NO WARRANTIES, EXPRESS OR IMPLIED, INCLUDING WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE. Some states do not permit limitation or exclusion of implied warranties; therefore, the aforesaid limitation(s) or exclusion(s) may not apply to the purchaser.

EXCEPT AS PROVIDED ABOVE, IN NO EVENT WILL TRIPP LITE BE LIABLE FOR DIRECT, INDIRECT, SPECIAL, INCIDENTAL OR CONSEQUENTIAL DAMAGES ARISING OUT OF THE USE OF THIS PRODUCT, EVEN IF ADVISED OF THE POSSIBILITY OF SUCH DAMAGE. Specifically, TRIPP LITE is not liable for any costs, such as lost profits or revenue, loss of equipment, loss of use of equipment, loss of software, loss of data, costs of substitutes, claims by third parties, or otherwise.

Warranty and Product Registration

PRODUCT REGISTRATION

Visit www.tripplite.com/warranty today to register your new Tripp Lite product. You'll be automatically entered into a drawing for a chance to win a FREE Tripp Lite product!*

*No purchase necessary. Void where prohibited. Some restrictions apply. See website for details.

Regulatory Compliance Identification Numbers

For the purpose of regulatory compliance certifications and identification, your Tripp Lite product has been assigned a unique series number. The series number can be found on the product nameplate label, along with all required approval markings and information. When requesting compliance information for this product, always refer to the series number. The series number should not be confused with the marketing name or model number of the product.

WEEE Compliance Information for Tripp Lite Customers and Recyclers (European Union)



Under the Waste Electrical and Electronic Equipment (WEEE) Directive and implementing regulations, when customers buy new electrical and electronic equipment from Tripp Lite they are entitled to:

- Send old equipment for recycling on a one-for-one, like-for-like basis (this varies depending on the country)
- Send the new equipment back for recycling when this ultimately becomes waste

Warranty and Product Registration

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.



1111 W. 35th Street, Chicago, IL 60609 USA
triplite.com/support



Manufacturing
Excellence.