

Quick Start Guide

3-Port USB-C Hub with Gigabit Ethernet, 100W PD Charging and QC Charging

Model: U460-003-3AGALC

USB Type-C® and USB-C® are registered trademarks of USB Implementers Forum.

Este manual está disponible en español en la página de Tripp Lite: tripplite.com

Ce manuel est disponible en français sur le site Web de Tripp Lite : tripplite.com

Русскоязычная версия настоящего руководства представлена на веб-сайте компании Tripp Lite по адресу: tripplite.com

Dieses Handbuch ist in deutscher Sprache auf der Tripp Lite-Website verfügbar: tripplite.com

WARRANTY REGISTRATION

Register your product today and be automatically entered to win an ISOBAR® surge protector in our monthly drawing!

tripplite.com/warranty



1111 W. 35th Street, Chicago, IL 60609 USA
tripplite.com/support

Copyright © 2021 Tripp Lite. All rights reserved.

Product Features

- 3 USB-A ports support USB 3.2 Gen 1 data transfer speeds up to 5 Gbps
- One USB port also supports charging up to 5V 1.5A (7.5W)
- USB-C PD Charging 3.0 port supports 20V 5A (100W) power output and Fast Role Swap for charging host device, as well as simultaneous data transmission at speeds up to 5 Gbps
- USB ports backward compatible with USB 2.0 legacy equipment
- RJ45 port allows connection to 10/100/1000 Mbps (1 Gbps) Gigabit Ethernet network
- Compact size allows convenient transport in a backpack or laptop bag for connections anywhere

Package Contents

- U460-003-3AGALC 3-Port USB-C Hub
- Quick Start Guide


Optional Accessories

- N201-Series Cat6 Gigabit Snagless Ethernet Cables
- U420-Series USB-C (USB 3.2 Gen 1) Cables, M/M

Operation

1. Connect the built-in USB-C cable to your MacBook, Chromebook or other USB-C host.
2. Connect the USB-C PD Charging port to your host device or an AC wall charger with a user-supplied USB cable (see **Optional Accessories**).
3. Connect USB peripherals, such as a thumb drive, mouse and keyboard, to the USB-A ports.
4. Connect the RJ45 port to a Gigabit Ethernet network or router with a user-supplied Ethernet cable (see **Optional Accessories**).
5. Automatically or manually set the host device's IP address.

Operation

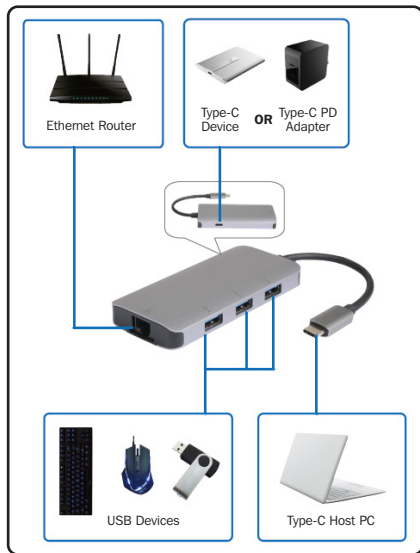

Specifications

Input/Output	
Input	USB-C (Male)
Output	(3x) USB-A (Female) USB-C PD Charging (Female) RJ45 (Female)
USB Version	USB 3.2 Gen 1 (5 Gbps)
PD Charging	100W PD Charging
Mechanical	
Size	3.7 x 1.8 x 0.5 in. / 95 x 45 x 13 mm
Weight	2.4 oz. / 68.5 g
Environmental	
Operating Temperature Range	32° to 113°F (0° to 45°C)
Storage Temperature Range	14° to 158°F (-10° to 70°C)
Operating Humidity Range	10 to 85% RH, Non-Condensing
Storage Humidity Range	5 to 90% RH, Non-Condensing
Warranty	
Limited Warranty	1 Year
Regulatory Approvals	
Certifications	FCC, CE, ICES, RoHS, REACH

Warranty and Product Registration

3-Year Limited Warranty

Seller warrants this product, if used in accordance with all applicable instructions, to be free from original defects in material and workmanship for a period of three (3) years from the date of initial purchase. If the product should prove defective in material or workmanship within that period, Seller will repair or replace the product, at its sole discretion.

THIS WARRANTY DOES NOT APPLY TO NORMAL WEAR OR TO DAMAGE RESULTING FROM ACCIDENT, MISUSE, ABUSE OR NEGLIGENCE. SELLER MAKES NO EXPRESS WARRANTIES OTHER THAN THE WARRANTY EXPRESSLY SET FORTH HEREIN. EXCEPT TO THE EXTENT PROHIBITED BY APPLICABLE LAW, ALL IMPLIED WARRANTIES, INCLUDING ALL WARRANTIES OF MERCHANTABILITY OR FITNESS, ARE LIMITED IN DURATION TO THE WARRANTY PERIOD SET FORTH ABOVE; AND THIS WARRANTY EXPRESSLY EXCLUDES ALL INCIDENTAL AND CONSEQUENTIAL DAMAGES. (Some states do not allow limitations on how long an implied warranty lasts, and some states do not allow the exclusion or limitation of incidental or consequential damages, so the above limitations or exclusions may not apply to you. This warranty gives you specific legal rights, and you may have other rights which vary from jurisdiction to jurisdiction.)

WARNING: The individual user should take care to determine prior to use whether this device is suitable, adequate or safe for the use intended. Since individual applications are subject to great variation, the manufacturer makes no representation or warranty as to the suitability or fitness of these devices for any specific application.

Warranty and Product Registration

Product Registration

Visit triplite.com/warranty today to register your new Tripp Lite product. You'll be automatically entered into a drawing for a chance to win a FREE Tripp Lite product!*

*No purchase necessary. Void where prohibited. Some restrictions apply. See website for details.

WEEE Compliance Information for Tripp Lite Customers and Recyclers (European Union)



Under the Waste Electrical and Electronic Equipment (WEEE) Directive and implementing regulations, when customers buy new electrical and electronic equipment from Tripp Lite, they are entitled to:

- Send old equipment for recycling on a one-for-one, like-for-like basis (this varies depending on the country)
- Send the new equipment back for recycling when this ultimately becomes waste

Use of this equipment in life support applications where failure of this equipment can reasonably be expected to cause the failure of the life support equipment or to significantly affect its safety or effectiveness is not recommended.

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.



1111 W. 35th Street, Chicago, IL 60609 USA
triplite.com/support